



Transformer



1M000000

Catalog Number

 


Type QL

9T10C1348G31


300.0 KVA 60 HZ 3 PH 5 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 480 VOLTS (LINE-LINE)
277 VOLTS (LINE-NEUTRAL)

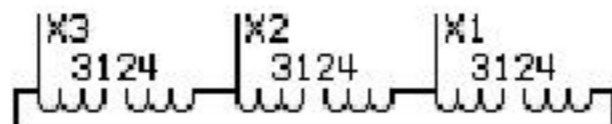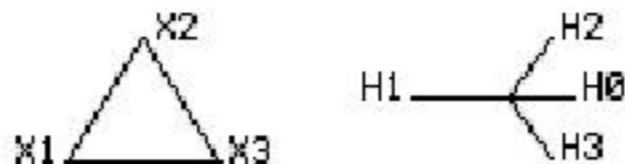

COIL TAP ARRANGEMENT

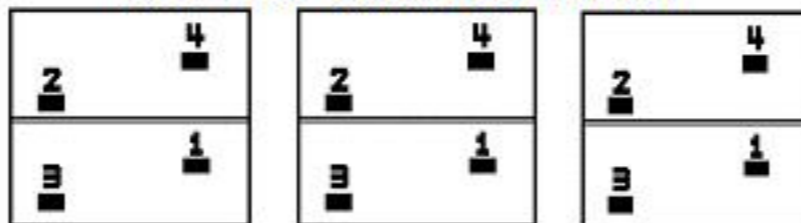

JUMPER CONNECTION

TAP	VOLTS
1-2	216
2-3	208
3-4	200

NET WGT
2150 LB
975.2 Kg

60800
DK76C
NOG
040416

INSPECTION
&
FINAL TEST
N615!




LISTED 769G

Assembled in Mexico


ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001 Outline:
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL 303B112GEDXP78C

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE

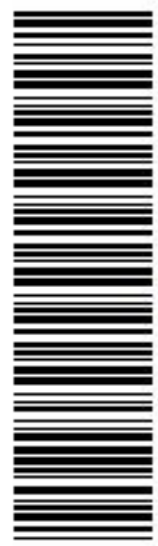

2M000000

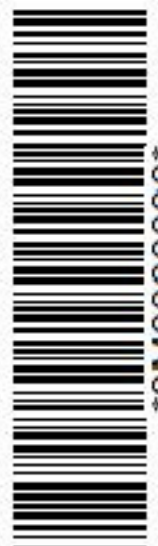

3M000000