



Transformer

—
by ABB



1M000000


Catalog Number 9T10C1446G31
Type QL

150.0 KVA 60 HZ 3 PH 3.4 % IMP
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C


JUMPER CONNECTION

TAP	VOLTS
1-2	221
2-3	214
3-4	208
4-5	200
5-6	194

PRIMARY (X) 208 VOLTS (LINE-LINE)
 SECONDARY (H) 220 VOLTS (LINE-LINE)
 127 VOLTS (LINE-NEUTRAL)

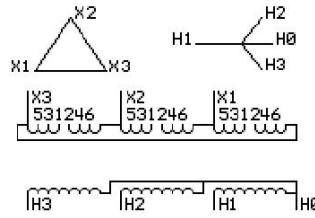

COIL TAP ARRANGEMENT

 

NET WGT 1610 LB
 730.3 Kg
 89746 DY77C

INSPECTION & FINAL TEST
 NOG N139!
 092021



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y107G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDYP77C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000