



Transformer

by ABB




1M000000

Catalog Number 9T10C1534 **Type** QL

75.0 KVA 60 HZ 3 PH 4.8 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 240 VOLTS (LINE-LINE)
SECONDARY (H) 480 VOLTS (LINE-LINE)
277 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	TAP VOLTS
1	250
2	246
3	240
4	233
5	229
6	220
7	215

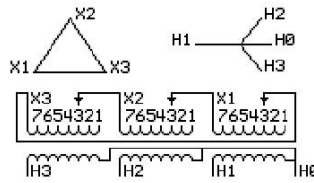


NET WGT
661 LB
299.8 Kg
89761
UY74C

INSPECTION & FINAL TEST
NOG
N139!
092021



 COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

H3 X3 H2 X2 H1 X1

 
 
Note: H0 at the bottom

Outline: 303B111GEUY74C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

H3 X3 H2 X2 H1 X1
 H3 X3 H2 X2 H1 X1
 H3 X3 H2 X2 H1 X1



H0