




\*1M000000\*

**Catalog Number** 9T10C1534G31 **Type QL**

75.0 KVA 60 HZ 3 PH 4.1 % IMP  
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 240 VOLTS (LINE-LINE)  
SECONDARY (H) 480 VOLTS (LINE-LINE)  
277 VOLTS (LINE-NEUTRAL)


JUMPER CONNECTION	TAP VOLTS
1	253
2	248
3	240
4	233
5	229
6	224
7	214

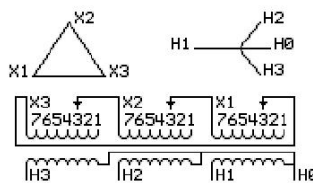

NET WGT 748 LB  
339.3 Kg  
89762 UX74C  
INSPECTION & FINAL TEST  
NOG N139!  
092021



**COIL TAP ARRANGEMENT**

 

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL  
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.  
CHECK ADDITIONAL NEC AND LOCAL CODE

H3 X3 H2 X2 H1 X1

Note: H0 at the bottom

Outline: 303B111GEUXP74C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

H3	X3	H2	X2	H1	X1
-	-	-	-	-	-
*2M000000*					
*3M000000*					