



Transformer

by ABB




1M000000

Catalog Number 9T10C1543 **Type** QL


45.0 KVA 60 HZ 3 PH 3.4 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 240 VOLTS (LINE-LINE)
SECONDARY (H) 480 VOLTS (LINE-LINE)

JUMPER CONNECTION TAP	VOLTS
1	251
2	247
3	240
4	233
5	229
6	222
7	215

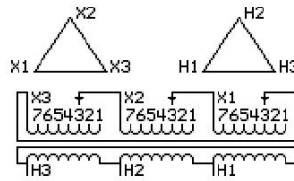

COIL TAP ARRANGEMENT

 

NET WGT 480 LB 217.7 Kg	INSPECTION & FINAL TEST NOG N137! 091021
88887 UX73C	



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

H3	X3	H2	X2	H1	X1	-
-	-	-	-	-	-	-

Note: standard

Outline: 303B111GEUXP73C

NEMA CLASS AA DRY TYPE TRANSFORMER

 
Meets DOE 2016 efficiency

H3 X3 H2 X2 H1 X1



2M000000

H3 X3 H2 X2 H1 X1



3M000000