



Transformer

by ABB




1M000000

Catalog Number 9T10C1544 **Type** QL


75.0 KVA 60 HZ 3 PH 4.4 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 240 VOLTS (LINE-LINE)
SECONDARY (H) 480 VOLTS (LINE-LINE)

JUMPER CONNECTION TAP	VOLTS
1	253
2	244
3	240
4	236
5	227
6	222
7	218

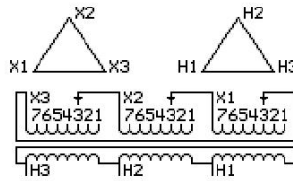

COIL TAP ARRANGMENT

 

NET WGT 661 LB 299.8 Kg 89764 UY74C	INSPECTION & FINAL TEST NOG N139! 092021
--	--



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

H3	X3	H2	X2	H1	X1
-	-	-	-	-	-

Note: standard

Outline: 303B111GEUY74C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

H3 X3 H2 X2 H1 X1



2M000000

H3 X3 H2 X2 H1 X1



3M000000