



Transformer

by ABB



1M000000

 

Catalog Number 9T10C1667 **Type** QL

225.0 KVA 60 HZ 3 PH 6 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 220 VOLTS (LINE-LINE)
SECONDARY (H) 380 VOLTS (LINE-LINE)
219 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION

TAP	VOLTS
1-2	234
2-3	227
3-4	220
4-5	212
5-6	205
6-7	197
7-8	190

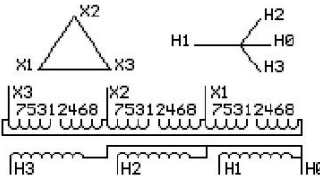

NET WGT
1847 LB
837.8 Kg
89777
DX77C

INSPECTION & FINAL TEST
NOG
N137!
091021



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

Note:

Outline: 303B112GEDXP77C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000