



Transformer

by ABB




1M000000

Catalog Number **Type QL**
9T10C1781G31


15.0 KVA 60 HZ 3 PH 3.9 % IMP
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 380 VOLTS (LINE-LINE)
SECONDARY (X) 220 VOLTS (LINE-LINE)

JUMPER CONNECTION	TAP	VOLTS
1	400	
2	390	
3	380	
4	370	
5	360	
6	352	
7	342	

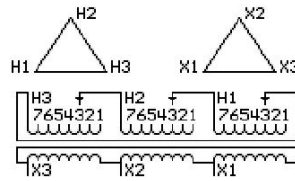

COIL TAP ARRANGEMENT

 

NET WGT
230 LB
104.3 Kg
89787
UX71C

INSPECTION & FINAL TEST
NOG
N139!
092021



X3 H3 X2 H2 X1 H1 - - - - -
X3 H3 X2 H2 X1 H1 - - - - -

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1071G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1 -

Note: standard

Outline: 303B111GEUXP71C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

