



Transformer

by ABB




1M000000

Catalog Number **Type QL**
9T10C1783G31


45.0 KVA 60 HZ 3 PH 3.6 % IMP
40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 380 VOLTS (LINE-LINE)
SECONDARY (X) 220 VOLTS (LINE-LINE)

JUMPER CONNECTION	TAP	VOLTS
1	400	
2	390	
3	380	
4	371	
5	361	
6	350	
7	343	

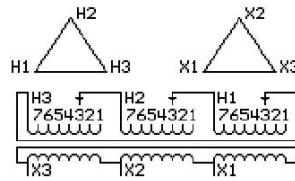

COIL TAP ARRANGEMENT

 

NET WGT	INSPECTION & FINAL TEST
480 LB	
217.7 Kg	NOG
88891	N137!
UX73C	091021



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1 -
 - - - - - - -
 Note: **standard**

Outline: 303B111GEUXP73C

NEMA CLASS AA DRY TYPE TRANSFORMER

 
Meets DOE 2016 efficiency

X3 H3 X2 H2 X1 H1



2M000000

X3 H3 X2 H2 X1 H1



3M000000