



Transformer

by ABB




1M000000

Catalog Number 9T10C1883
Type QL


45.0 KVA 60 HZ 3 PH 3.5 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 440 VOLTS (LINE-LINE)
SECONDARY (X) 220 VOLTS (LINE-LINE)
127 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	
TAP	VOLTS
1	462
2	452
3	440
4	430
5	416
6	406
7	395

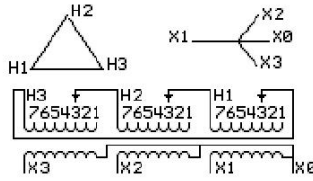

COIL TAP ARRANGEMENT

 

NET WGT	INSPECTION & FINAL TEST
480 LB	
217.7 Kg	NOG
88894	N137!
UX73C	091021



X3 H3 X2 H2 X1 H1 -
-
-
-
X3 H3 X2 H2 X1 H1 -
-
-
X0

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1 -

Note: X0 at the top

Outline: 303B111GEUXP73C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

