



Transformer

by ABB




1M000000

Catalog Number **Type QL**
9T10C1991


15.0 KVA 60 HZ 3 PH 4.2 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 230 VOLTS (LINE-LINE)
SECONDARY (H) 400 VOLTS (LINE-LINE)
231 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	
TAP	VOLTS
1	241
2	235
3	230
4	225
5	219
6	213
7	207

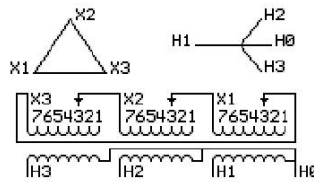

COIL TAP ARRANGEMENT

 

NET WGT
230 LB
104.3 Kg
89800
UX71C

INSPECTION & FINAL TEST
NOG
N139!
092021



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1071G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

ASSEMBLED IN MEXICO

H3 X3 H2 X2 H1 X1 H0

Note: **standard**

Outline: 303B111GEUXP71C

