



Transformer

by ABB




1M000000

Catalog Number 9T10C1993 **Type** QL

45.0 KVA 60 HZ 3 PH 3.2 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 230 VOLTS (LINE-LINE)
SECONDARY (H) 400 VOLTS (LINE-LINE)
231 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION	TAP VOLTS
1	242
2	234
3	230
4	223
5	220
6	213
7	206

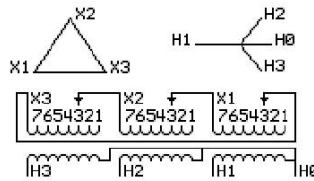


NET WGT
480 LB
217.7 Kg
88896
UX73C

INSPECTION & FINAL TEST
NOG
N137!
091021



 COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

H3 X3 H2 X2 H1 X1 -
 - - - - -
 Note: H0 at the top

Outline: 303B111GEUXP73C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

H3 X3 H2 X2 H1 X1 -
 - - - - -
 H3 X3 H2 X2 H1 X1 -
 - - - - -
 H0

2M000000

3M000000