



Transformer

by ABB




1M000000

Catalog Number 9T10C2094G02 **Type** QL

75.0 KVA 60 HZ 3 PH 4.8 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

JUMPER CONNECTION TAP	VOLTS
1	419
2	411
3	400
4	389
5	381
6	372
7	359

PRIMARY (H) 400 VOLTS (LINE-LINE)
SECONDARY (X) 400 VOLTS (LINE-LINE)
231 VOLTS (LINE-NEUTRAL)

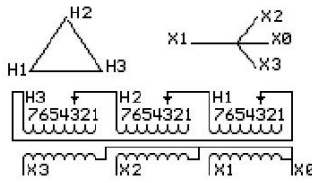


NET WGT
661 LB
299.8 Kg
INSPECTION & FINAL TEST
NOG
N139!
UY74C
092021



LISTED 769G

 COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1074G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1

Note: X0 at the bottom

Outline: 303B111GEUYP74C

 
NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X3 H3 X2 H2 X1 H1
X3 H3 X2 H2 X1 H1
X0



2M000000



3M000000