



Transformer

by ABB



1M000000


Catalog Number 9T10C2402 **Type** QL

30.0 KVA 60 HZ 3 PH 3.6 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C


PRIMARY (H) 600 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
120 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION

TAP	VOLTS
1	631
2	616
3	600
4	585
5	570
6	554
7	539

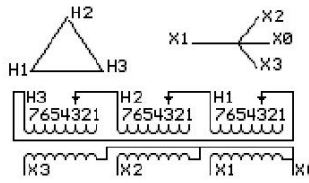

COIL TAP ARRANGEMENT

 

NET WGT
353 LB
160.1 Kg
89838
UX72C

INSPECTION & FINAL TEST
NOG
N139!
092021



LISTED 769G

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1072G06

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

X3	H3	X2	H2	X1	H1	X0
-	-	-	-	-	-	-

Note: standard

Outline: 303B111GEUXP72C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X3 H3 X2 H2 X1 H1 X0
 X3 H3 X2 H2 X1 H1 X0
 X3 H3 X2 H2 X1 H1 X0



2M000000



3M000000