



Transformer



1M0000000

Catalog Number **9T10Z1003** Type **QL**

45.0 KVA 60 HZ 3 PH 3.3 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
120 VOLTS (LINE-NEUTRAL)

| JUMPER CONNECTION | |
|-------------------|-------|
| TAP | VOLTS |
| 1 | 502 |
| 2 | 491 |
| 3 | 480 |
| 4 | 469 |
| 5 | 455 |
| 6 | 444 |
| 7 | 433 |

NET WGT
480 LB
217.7 Kg

59178
UX73C
NOG
012716

INSPECTION
&
FINAL TEST
N605!

COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20) OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1172G06

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001 Outline:
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL 303B111GEUXP73C

X3 H3 X2 H2 X1 H1 -


IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE

Note: X0 at the top

X3 H3 X2 H2 X1 H1 -

X3 H3 X2 H2 X1 H1 -

X0

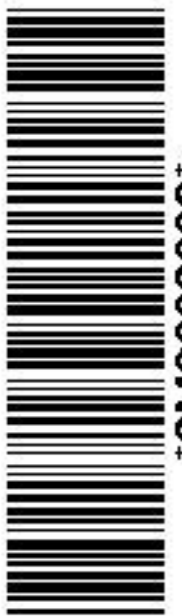

2M0000000



3M0000000