




1M000000

Catalog Number Type QL **9T11C1456G03**

150.0 KVA 60 HZ 3 PH 4.2 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

JUMPER CONNECTION	
TAP	VOLTS
1-2	221
2-3	215
3-4	208
4-5	202
5-6	196


PRIMARY (H) 208 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

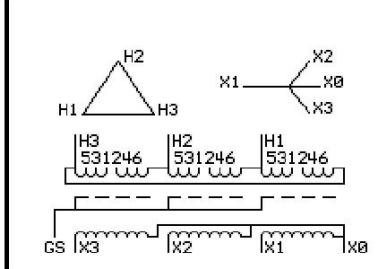

NET WGT 1610 LB 730.3 Kg 89984 DY77C	INSPECTION & FINAL TEST NOG N139! 092021
---	--



 COIL TAP ARRANGEMENT



ELECTROSTATIC GROUND SHIELD IN EACH PHASE

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD 9T18Y1077G06
SUITABLE FOR NONSINUSOIDAL CURRENT LOAD WITH K-FACTOR NOT TO EXCEED 13
BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
CHECK ADDITIONAL NEC AND LOCAL CODE

ASSEMBLED IN MEXICO

Note:

Outline: 303B112GEDYP77C

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

