



Servicenter

—
by ABB



1M000000

Catalog Number
9T17A0011


Type QL-
WP

15.0 KVA 60 HZ 3 PH 3.7 % IMP
40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

Note: Design is based on 15.00KVA & 115C Rise 3.4% Imp.

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
120 VOLTS (LINE-NEUTRAL)

JUMPER CONNECTION TAP VOLTS
1 504
2 493
3 480
4 468
5 455
6 445
7 432

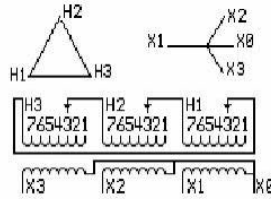


NET WGT
231 LB
104.8 Kg
85468

UX71A
NOG
060421

INSPECTION &
FINAL TEST
N123!



 COIL TAP ARRANGEMENT



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE

ASSEMBLED IN MEXICO

X3 H3 X2 H2 X1 H1 X0

Note: standard

Outline: 303B424AAP015

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X0

H1

X1

H2

X2

 
 
H3

X3

X0

X0

X0



X0

H1

X1

H2

X2

H3

X3

X0

X0

X0