



Servicenter



1M000000

X0
X1
H1
H2
X2
X3

X0

X1
H1
H2
X2
X3



3M000000



2M000000

Catalog Number
9T17S0022


Type QL-WP

22.5 KVA 60 HZ 3 PH 4 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

Note: Design is based on 30.00KVA & 150C Rise 5.4% Imp.

PRIMARY (H) 600 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
120 VOLTS (LINE-NEUTRAL)

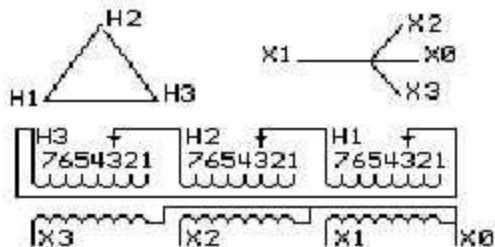

JUMPER CONNECTION	
TAP	VOLTS
1	630
2	614
3	600
4	584
5	570
6	554
7	540


NET WGT
330 LB
149.7 Kg

53715
UX72A

NOG
063016

INSPECTION
&
FINAL TEST
N627!

COIL TAP ARRANGEMENT

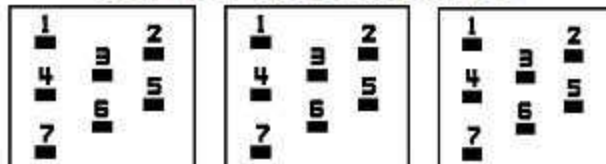

LISTED 769G

Assembled in Mexico

ENCLOSURE TYPE 2 (IP20). OR RAINPRO-OF TYPE 3R (IP22) WHEN PROVIDED SHIELD

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP008
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

Outline: 303B-424SSP022

X3 H3 X2 H2 X1 H1 X0

Note: standard

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE