



# Servicenter



\*1M000000\*

Catalog Number

9T17S0023


Type QL-WP

30.0 KVA 60 HZ 3 PH 5.4 % IMP


40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

Note: Design is based on 30.00KVA & 150C Rise 5.4% Imp.

PRIMARY (H) 600 VOLTS (LINE-LINE)  
SECONDARY (X) 208 VOLTS (LINE-LINE)  
120 VOLTS (LINE-NEUTRAL)

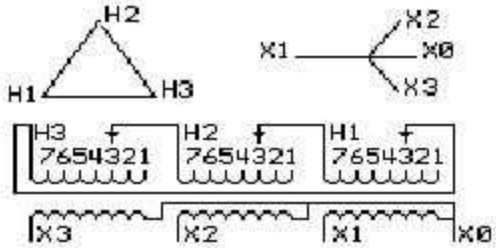

### COIL TAP ARRANGEMENT

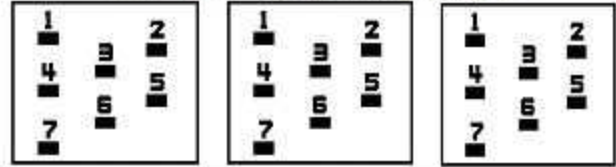

JUMPER CONNECTION	
TAP	VOLTS
1	630
2	614
3	600
4	584
5	570
6	554
7	540

NET WGT  
330 LB  
149.7 Kg  
  
53715  
UX72A  
NOG  
063016

INSPECTION & FINAL TEST  
N627!



LISTED 769G

Assembled in Mexico

ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP008  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

Outline: 303B-424SSP030


IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODE

X3 H3 X2 H2 X1 H1 X0


- - - - -

Note: standard

X0  
X1 H1  
X2 H2  
X3 H3  
X1 H1  
X2 H2  
X3 H3

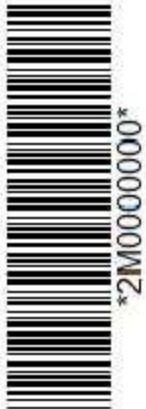

\*2M000000\*

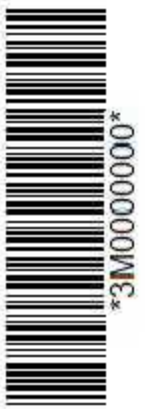

\*3M000000\*