



Transformer

Catalog Number TYPE QL


9T23B2683

50.0 KVA 60 HZ 1 PH 5.2 % IMP



40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY LINES ON H1-H2	
VOLTS	CONNECT
536	8-7
552	7-6
568	6-5
584	5-4
600	4-3
616	3-2
632	2-1

SECONDARY LINES ON X1-X4	
VOLTS	CONNECT
120	X1-X3, X2-X4
240	X2-X3

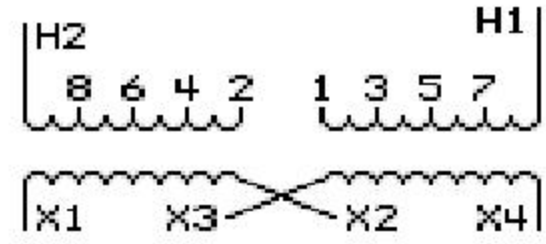

COIL TAP ARRANGEMENT

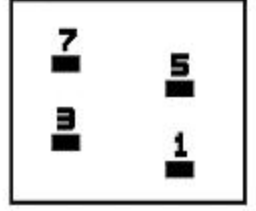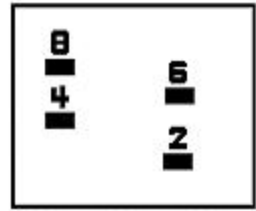

LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G06

Outline: 303B904AAP073

INSPECTION &
FINAL TEST
N731&

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

080107

NET WGT
340 LB

Assembled in Mexico 1159



1M0000000



2M0000000



2M0000000