



Transformer

Catalog Number


TYPE QL

9T23B3012

50.0 KVA 60 HZ 3 PH 3.5 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C


PRIMARY (H)	480 VOLTS (LINE-LINE)
SECONDARY (X)	480 VOLTS (LINE-LINE)
	277 VOLTS (LINE-NEUTRAL)

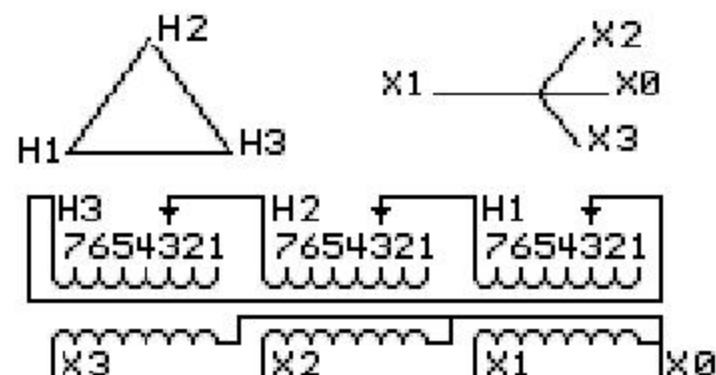

JUMPER CONNECTION

TAP	VOLTS
1	504
2	491
3	480
4	468
5	454
6	445
7	432

COIL TAP ARRANGEMENT

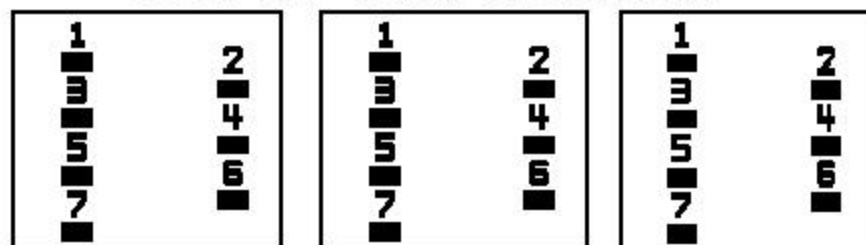

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G06

Outline: 303B900AAP007

INSPECTION &
FINAL TEST
N731&

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

080107

NET WGT
505 LB

Assembled in Mexico 1390



1M000000



2M000000



2M000000