



Transformer

by ABB




1M000000

Catalog Number **9T33A2673** Type QL


50.0 KVA 60 HZ 1 PH 5.4 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY LINES ON H1-H2		SECONDARY LINES ON X1-X4	
VOLTS	CONNECT	VOLTS	CONNECT
215	8-H1,7-H2	429	8-7
227	6-H1,5-H2	442	7-6
240	4-H1,3-H2	455	6-5
253	2-H1,1-H2	467	5-4
		480	4-3
		493	3-2
		505	2-1
		SECONDARY LINES ON X1-X2-X4	
		VOLTS	CONNECT
		120/240	X2-X3

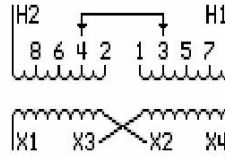

COIL TAP ARRANGEMENT

 

NET WGT 490 LB
222.3 Kg
90124
XV173

NOG O91021
INSPECTION &
FINAL TEST
N137!



X3	X1	-	X2	X4	-	H1
X3	X1	-	X2	X4	-	H1
X3	X1	-	X2	X4	-	H1

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y1071G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

ASSEMBLED IN MEXICO

X3 X1 - X2 X4 -

- - H2 - - H1

Note: **Standard**

Outline: 303B409CAP073

NEMA CLASS AA DRY TYPE TRANSFORMER

Energy Efficiency in accordance with CSA C802.2-18 and DOE 2016

