



Transformer


Catalog Number 9T61C9878G03

9Q3C300AAAA13A2T00

300.0 KVA 60 HZ 3 PH 2.4 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

Note: Design is based on 500.0KVA & 150C Rise 4% Imp.

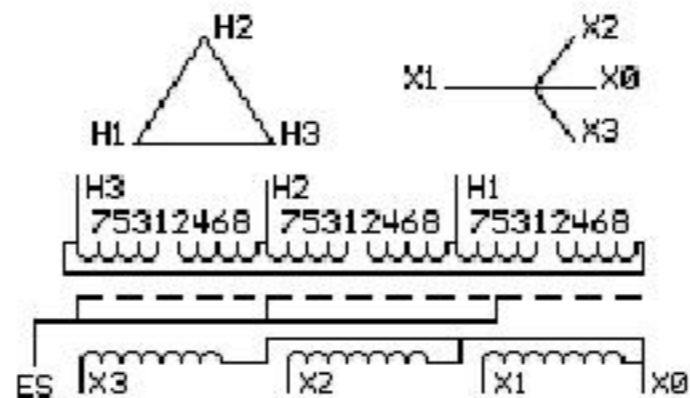


JUMPER CONNECTION

TAP	VOLTS
1-2	502
2-3	491
3-4	480
4-5	469
5-6	459
6-7	448
7-8	437

PRIMARY (H) 480 VOLTS (LINE-LINE)
 SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

COIL TAP ARRANGEMENT

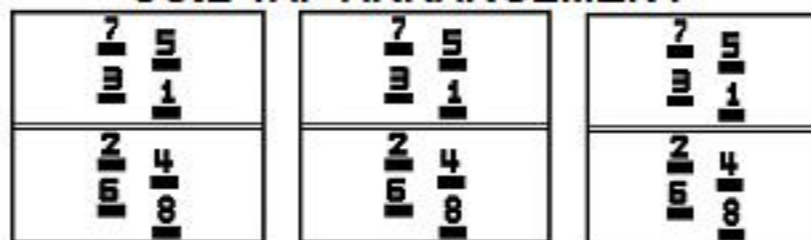

NET WGT 4050 LB 1837.1 Kg

090115 N536! YF379

55826 NOG



ELECTROSTATIC GROUND SHIELD IN EACH PHASE

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G68

SUITABLE FOR NONSINUSOIDAL CURRENT LOAD WITH K-FACTOR NOT TO EXCEED 13 BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL



LISTED 769G

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

Outline: 3038919AAP179
Assembled in Mexico

INSPECTION & FINAL TEST
N536!