



Transformer

NEMA
Premium



1M000000

X4

X4

Catalog Number
9T73C9844G13

TYPE **QL**


Ultra Efficient

NSALE0 300.000480C
+2,-4 2.30%
208Y/120

NET WGT
685 LB
310.7 Kg

75.0 KVA 60 HZ 3 PH 6.4 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

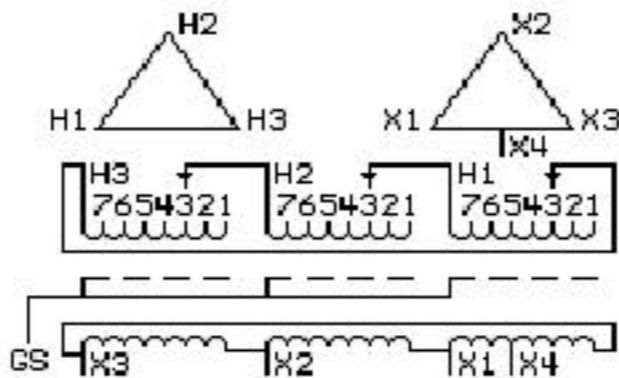

NN
N9T18Y4322G68T
TRANSFORMER N
ON-SIN K=04H0
0

57048
S34AC
NOG
091015

520

INSPECTION
&
FINAL TEST
N537!

X3 - X2 - X1 -

- H3 - H2 - H1

X3 - X2 - X1 -

- H3 - H2 - H1




9T64B3148G039T64B3148G03

150910IG2 303B918AAP079 YNNN 40115

220IS-19COL 3 60AL101034Y300.0 2.6 34
00 480(+2,-4 2.3

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

COIL TAP ARRANGEMENT

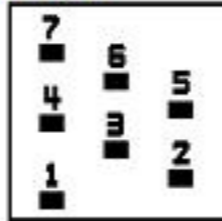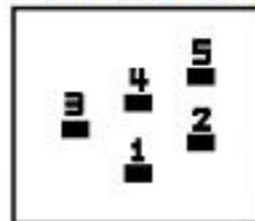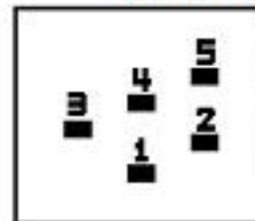

LISTED 769G

Assembled in Mexico

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G06

REDUCED CAPACITY TAP RATED AT 5% OF 3 PH KVA

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

Outline: 303B4-21AAP074

COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL


**IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.**

**X3 - X2 - X1 - X4
- H3 - H2 - H1**

Note: Mid-Tap



2M000000

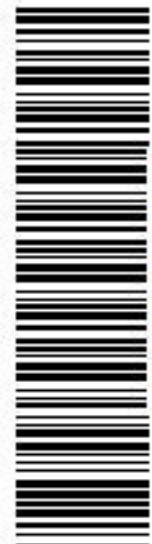

3M000000