

GE Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M000000

Catalog Number
9T76H9874G13

Type QL

75.0 KVA 60 HZ 3 PH 3.3 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
120 VOLTS (LINE-NEUTRAL)

ELECTROSTATIC GROUND SHIELD IN EACH PHASE


ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G06

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL


IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

GE Energy Industrial Solutions

NOT FOR SALE FOR USE IN THE UNITED STATES

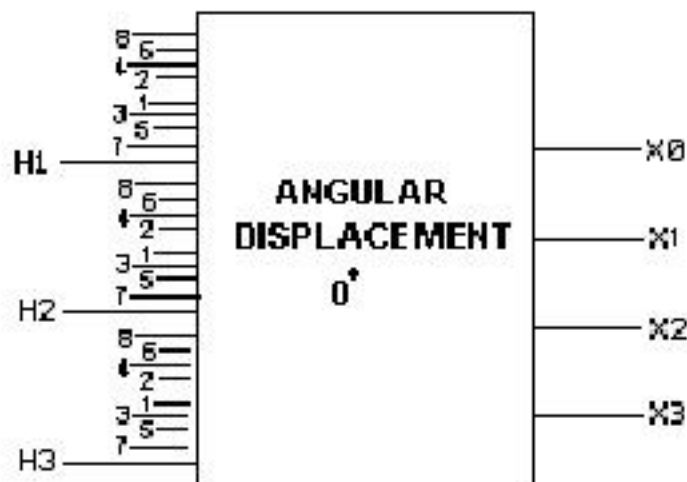

COIL TAP ARRANGEMENT

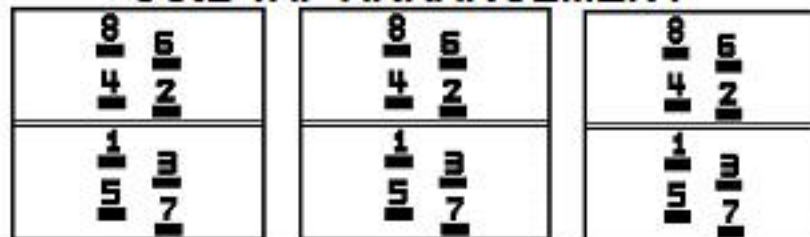

JUMPER CONNECTION	
TAP	VOLTS
1-2	503
2-3	494
3-4	480
4-5	468
5-6	455
6-7	442
7-8	433

NET WGT
990 LB
449.1 Kg

53925
H374C

NOG
033016

INSPECTION
&
FINAL TEST
N614!



LISTED 769G

Assembled in Mexico


X3 - X2 - X1 - -
- H3 - H2 - H1

Note: X0 Terminal at the bottom

X1 - -
X2 - - H1
X3 - - H3 - H2 - H1
X1 - -
X2 - - H1
X3 - - H3 - H2 - H1
X0



2M000000

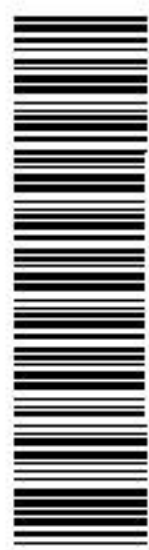

3M000000