



Transformer

NEMA
Premium


Catalog Number 9T76H9876G23

150.0 KVA 60 HZ 3 PH 3.5 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C Type: Q1

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

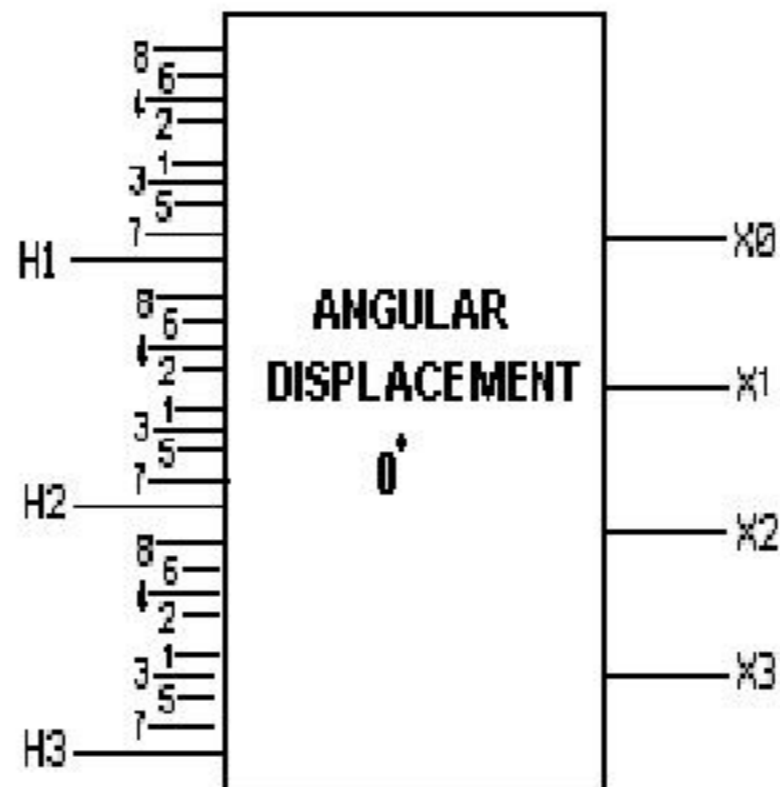

JUMPER
CONNECTION

| TAP | VOLTS |
|-----|-------|
| 1-2 | 505 |
| 2-3 | 494 |
| 3-4 | 480 |
| 4-5 | 466 |
| 5-6 | 455 |
| 6-7 | 444 |
| 7-8 | 433 |

COIL TAP ARRANGEMENT



NET WGT 2000 LB 907.2 Kg

100715 N541! M376C
57930 NOG



ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G79

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B931SLP076 INSPECTION & FINAL TEST
Assembled in Mexico N541!