



Transformer



NEMA CLASS AA DRY TYPE TRANSFORMER

Catalog Number
9T76H9877G03


225.0 KVA 60 HZ 3 PH 4.8 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
120 VOLTS (LINE-NEUTRAL)

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

NOT FOR SALE FOR USE IN THE UNITED STATES

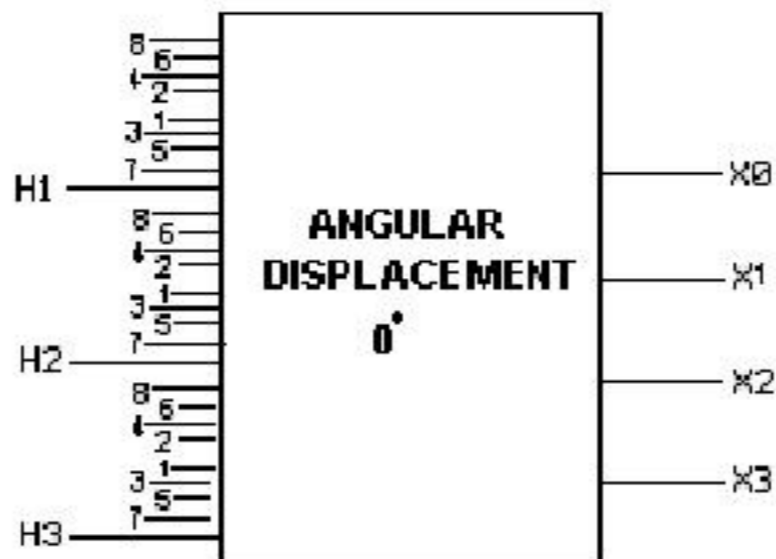

JUMPER CONNECTION	
TAP	VOLTS
1-2	504
2-3	489
3-4	480
4-5	467
5-6	452
6-7	445
7-8	431

COIL TAP ARRANGEMENT



NET WGT 1700 LB 771.1 Kg

010416 N602! XV377
58930 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B931SLP077
Assembled in Mexico

INSPECTION & FINAL TEST
N602!

