



Transformer


by ABB



1M000000

Catalog Number 9T76H9878G03
 Type QL
 300.0 KVA 60 HZ 3 PH 7.6 % IMP
 40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

JUMPER CONNECTION
 TAP VOLTS
 1-2 505
 2-3 494
 3-4 480
 4-5 466
 5-6 455
 6-7 444
 7-8 433

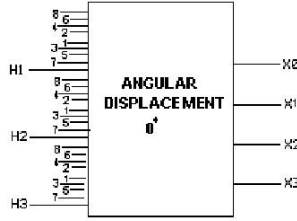


NET WGT 3150 LB
 1428.8 Kg
 87778
 YF378
 NOG
 043021
 INSPECTION &
 FINAL TEST
 N118!



PRIMARY (H) 480 VOLTS (LINE-LINE)
 SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

 COIL TAP ARRANGEMENT



ELECTROSTATIC GROUND SHIELD IN EACH PHASE

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD
 9T18Y4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP009
 COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
 CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

ASSEMBLED IN MEXICO

Note:

 
Outline: 303B931SLP078

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency



2M000000



3M000000