



Transformer

NEMA
Premium

Catalog Number
9T77H9873G03

45.0 KVA 60 HZ 3 PH 4.7 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL


PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4317G06


BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

**IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES
CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.**

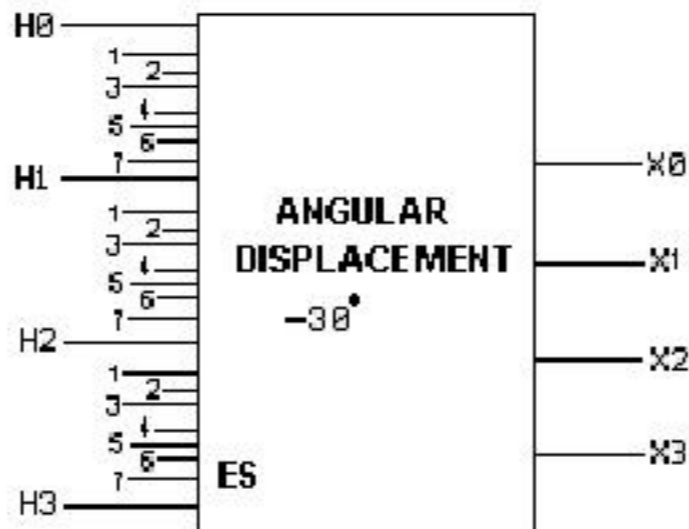

JUMPER CONNECTION	
TAP	VOLTS
1	504
2	492
3	480
4	467
5	455
6	443
7	431

COIL TAP ARRANGEMENT

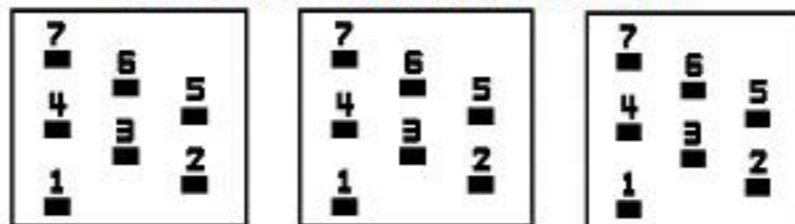

NET WGT 640 LB 290.3 Kg

033016 N614! H373C
60774 NOG



LISTED 769G

Outline: 303B431SLP073
Assembled in Mexico

INSPECTION & FINAL TEST
N614!

