



Transformer

NEMA
Premium

NEMA CLASS AA DRY TYPE TRANSFORMER

Catalog Number
9T77H9875G13


112.5 KVA 60 HZ 3 PH 3.5 % IMP

40 C AMB. 115 C RISE 220 C SYSTEM IS-19C Type: QL

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

ELECTROSTATIC GROUND SHIELD IN EACH PHASE


NOT FOR SALE FOR USE IN THE UNITED STATES

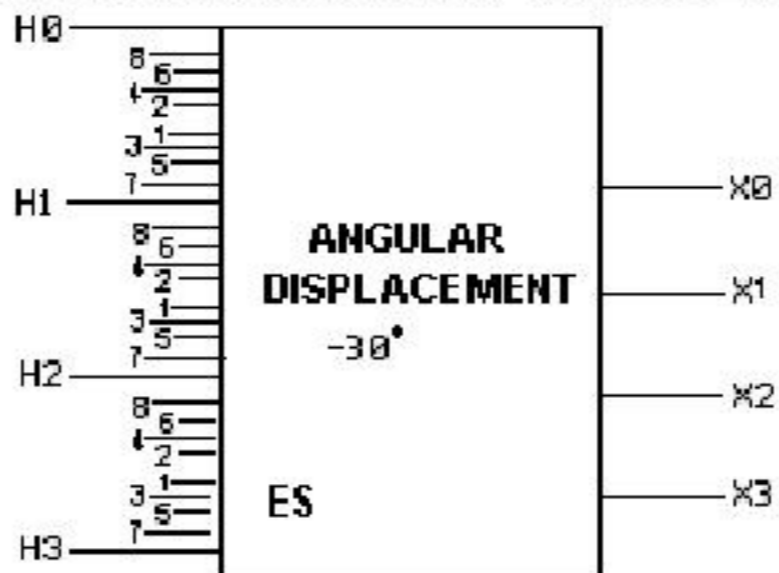

JUMPER CONNECTION

TAP	VOLTS
1-2	505
2-3	488
3-4	480
4-5	471
5-6	454
6-7	446
7-8	428

COIL TAP ARRANGEMENT

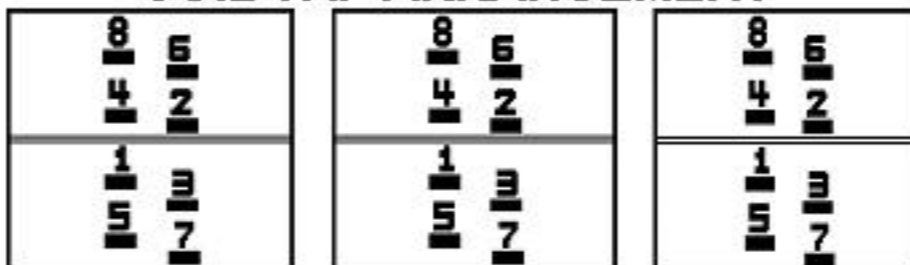

NET WGT 1845 LB 836.9 Kg

010416 N602! H375C
 58939 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B931SLP075
Assembled in Mexico

INSPECTION & FINAL TEST
N602!

