



Transformer



NEMA CLASS AA DRY TYPE TRANSFORMER

Catalog Number
9T77H9878G03


300.0 KVA 60 HZ 3 PH 7.6 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

NOT FOR SALE FOR USE IN THE UNITED STATES

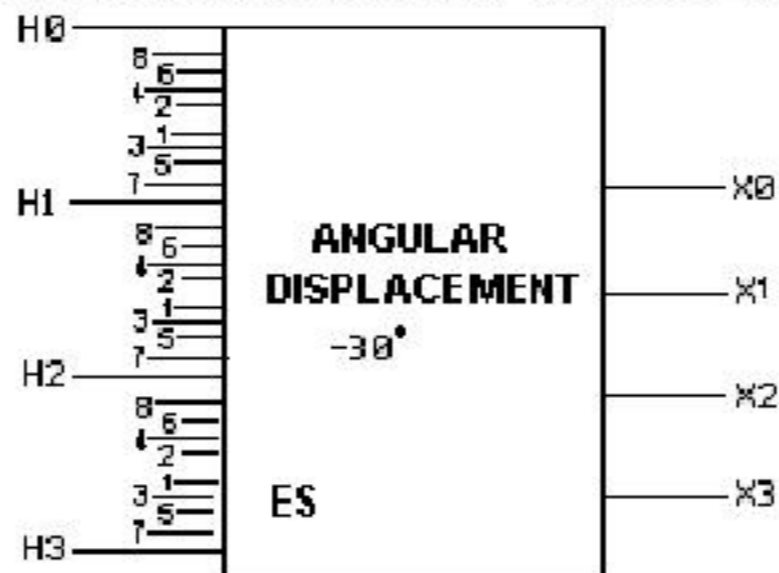

JUMPER CONNECTION

| TAP | VOLTS |
|-----|-------|
| 1-2 | 500 |
| 2-3 | 490 |
| 3-4 | 480 |
| 4-5 | 471 |
| 5-6 | 452 |
| 6-7 | 442 |
| 7-8 | 432 |

COIL TAP ARRANGEMENT



NET WGT 3150 LB 1428.8 Kg

010416 N602! YF378
58940 NOG

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
COPPER CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B931SLP078
Assembled in Mexico

INSPECTION & FINAL TEST
N602!

