



Transformer



Catalog Number **9Q1A015YAS01A03RL0T** Type **QL**


9Q1A015YAS01A03RL0T

9T83B2100G62

15.0 KVA 60 HZ 1 PH 3.4 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

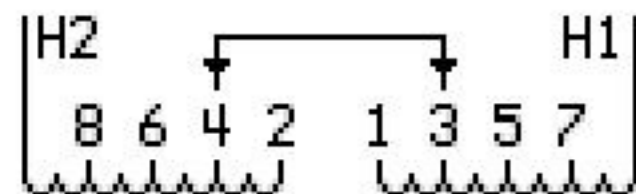

PRIMARY				SECONDARY	
LINES ON H1-H2				LINES ON X1-X4	
UOLTS	CONNECT	UOLTS	CONNECT	UOLTS	CONNECT
198	8-H1,7-H2	396	8-7	120	X1-X3,X2-X4
210	6-H1,5-H2	408	7-6	240	X2-X3
220	4-H1,3-H2	420	6-5		
231	2-H1,1-H2	429	5-4		
		440	4-3		
		450	3-2		

NET WGT
320 LB
145.2 Kg

50022
070115

INSPECTION
&
FINAL TEST
N5271

COIL TAP ARRANGEMENT



LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R. ENCLOSURE (IP32) WHEN PROVIDED SHIELD. 9T18Y4317G05

Outline: 303B406AAP071 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X3 - X4 - X2 - X1

- H2 - H1 - -

Note: Standard

X1 - - -

X2 - - -

- H1 - - -

X4 - H2 - X4 - H1

X3 - - -

X3 - - -

X3 - H2 - H1 - -

X3 - X4 - X2 - X1

- H2 - H1 - -

2M000000

3M000000