



# Transformer




Catalog Number Type QL

9T83B2101

25.0 KVA 60 HZ 1 PH 5.6 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

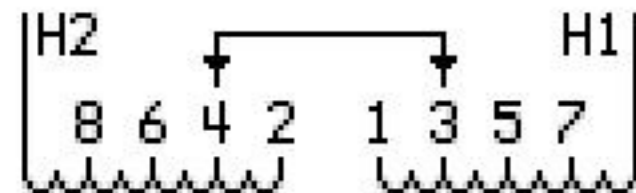

PRIMARY			
UOLTS	CONNECT	UOLTS	CONNECT
198	8-H1,7-H2	396	8-7
210	6-H1,5-H2	408	7-6
220	4-H1,3-H2	420	6-5
231	2-H1,1-H2	429	5-4
		440	4-3
		450	3-2

SECONDARY			
LINES ON X1-X4			
UOLTS	CONNECT	UOLTS	CONNECT
120	X1-X3,X2-X4		
240	X2-X3		

NET WGT  
320 LB  
145.2 Kg



50022

070115

INSPECTION  
&  
FINAL TEST

N5271

COIL TAP ARRANGEMENT

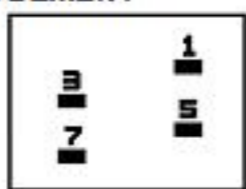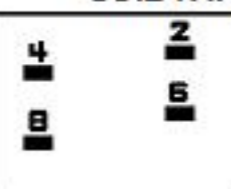

LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G05

Outline: 303B406AAP071 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X3 - X4 - X2 - X1

- H2 - H1 - -

Note: Standard

X1 -  
X2 -  
X3 -  
X4 -  
H1 -  
H2 -

