



# Transformer




Catalog Number **9T83B2121** Type **QL**

**9T83B2121**

**25.0 KVA 60 HZ 1 PH 5.7 % IMP**

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

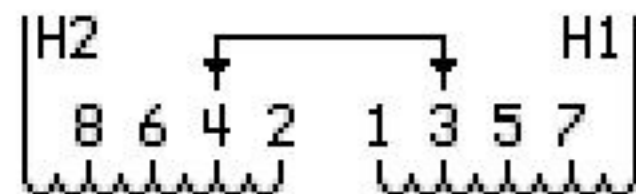

PRIMARY			
UOLTS	CONNECT	UOLTS	CONNECT
189	8-H1,7-H2	378	8-7
198	6-H1,5-H2	387	7-6
210	4-H1,3-H2	396	6-5
222	2-H1,1-H2	408	5-4
		420	4-3
		432	3-2

SECONDARY			
LINES ON X1-X4			
UOLTS	CONNECT	UOLTS	CONNECT
120	X1-X3,X2-X4		
240	X2-X3		

NET WGT  
320 LB  
145.2 Kg



50025

070115

INSPECTION  
&  
FINAL TEST

N5271

COIL TAP ARRANGEMENT

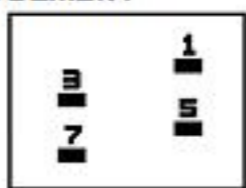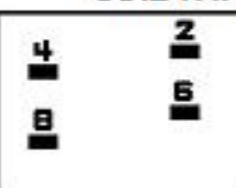

LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R. ENCLOSURE (IP32) WHEN PROVIDED SHIELD. 9T18Y4317G05

Outline: 303B406AAP071 Assembled in Mexico


BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X3 - X4 - X2 - X1

- H2 - H1 - -

Note: Standard

X1 -  
X2 -  
X3 -  
X4 -  
H1 -  
H2 -

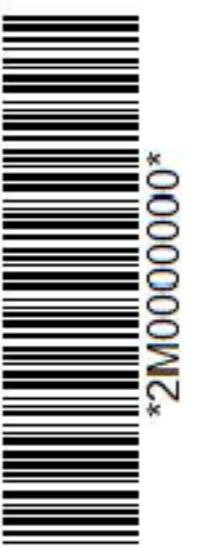

X1 -  
X2 -  
X3 -  
X4 -  
H1 -  
H2 -