



# Transformer



Catalog Number **9Q1A025AEAB00A2T00** Type QL

9T83B2151

**25.0 KVA 60 HZ 1 PH 5.8 % IMP**


40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG


PRIMARY		SECONDARY	
VOLTS	CONNECT	VOLTS	CONNECT
216	14-X1,13-X2	240	H1-H3,H2-H4
222	12-X1,11-X2	480	H2-H3
228	10-X1,9-X2		
234	8-X1,7-X2		
240	6-X1,5-X2		
246	4-X1,3-X2		
252	2-X1,1-X2		

NET WGT  
320 LB  
145.2 Kg  
  
50033  
070115

INSPECTION  
&  
FINAL TEST  
N5271

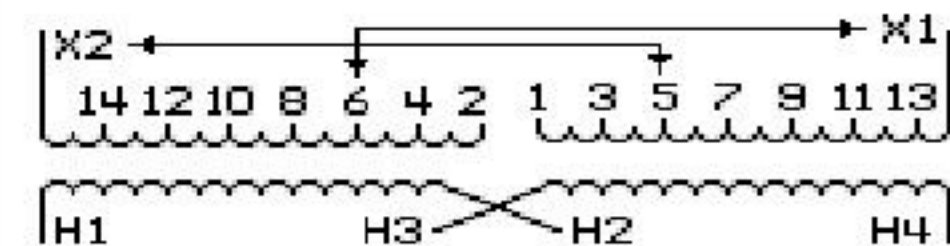

COIL TAP ARRANGEMENT

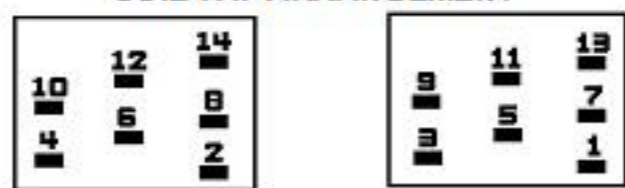

LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G05

Outline: 303B406AAP071 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

H3 - H4 - H2 - H1  
- X2 - X1 - -

Note: Standard

H1 -  
H2 -  
H3 -  
H4 -  
X1 -  
X2 -



H1 -  
H2 -  
H3 -  
H4 -  
X1 -  
X2 -

