



Transformer



1M000000

Catalog Number Type QL

9Q1A100AEAB00A2T00

9T83B2155

100.0 KVA 60 HZ 1 PH 6.7 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

PRIMARY
LINES ON X1-X2

VOLTS	CONNECT
218	14-X1,13-X2
224	12-X1,11-X2
229	10-X1,9-X2
235	8-X1,7-X2
240	6-X1,5-X2
245	4-X1,3-X2
251	2-X1,1-X2

SECONDARY
LINES ON H1-H4

VOLTS	CONNECT
240	H1-H3,H2-H4
480	H2-H3

NET WGT

900 LB

408.2 Kg

YF175

35844


123015

INSPECTION


&

FINAL TEST

N553!

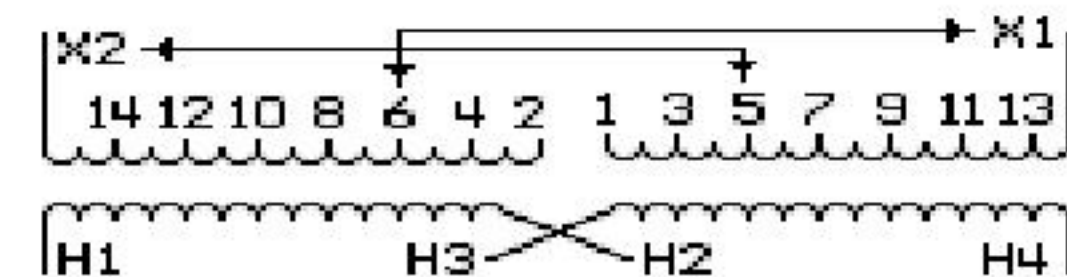

COIL TAP ARRANGEMENT

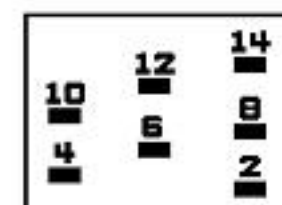

ENCLOSURE TYPE 2 (IP20) RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4322G77

Outline: 303B932AAP075 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



2M0000000



3M0000000