



# Transformer




Catalog Number **9Q1A015AXAS00C2T30** Type **QL**

**9T83B2670G90**

**15.0 KVA 60 HZ 1 PH 2.9 % IMP**

**40 C AMB. 80 C RISE 220 C SYSTEM IS-19C**

**NOG**

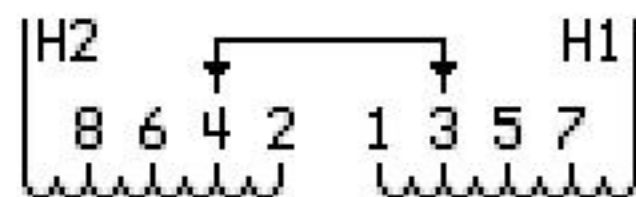

PRIMARY LINES ON H1-H2			
UOLTS	CONNECT	UOLTS	CONNECT
216	8-H1,7-H2	432	8-7
228	6-H1,5-H2	444	7-6
240	4-H1,3-H2	456	6-5
252	2-H1,1-H2	468	5-4
		480	4-3
		492	3-2

SECONDARY LINES ON X1-X4			
UOLTS	CONNECT	UOLTS	CONNECT
120	X1-X3,X2-X4		
240	X2-X3		

NET WGT  
320 LB  
145.2 Kg



50069

070115

INSPECTION  
&  
FINAL TEST

N5271

COIL TAP ARRANGEMENT

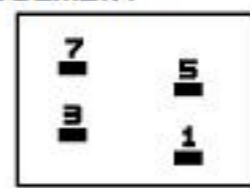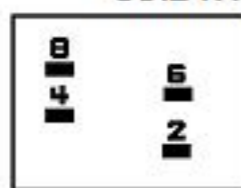

LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R. ENCLOSURE (IP32) WHEN PROVIDED SHIELD. 9T18Y4317G05

Outline: 303B406AAP071 Assembled in Mexico


BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

**X3 - X4 - X2 - X1**

**- H2 - H1 - -**

Note: Standard

X1 -  
X2 -  
X3 -  
X4 -  
H1 -  
H2 -

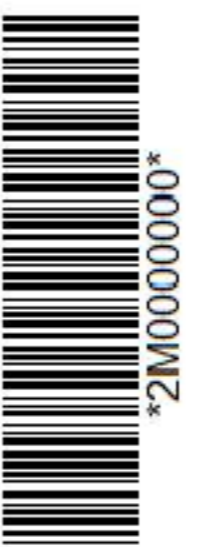

\*2M000000\*

X1 -  
X2 -  
X3 -  
X4 -  
H1 -  
H2 -



\*3M000000\*