

GE Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



1M000000

Catalog Number


Type QL

9T83B2675G80

100.0 KVA 60 HZ 1 PH 4.2 % IMP

40 C AMB. 80 C RISE 220 C SYSTEM IS-19C

NOG

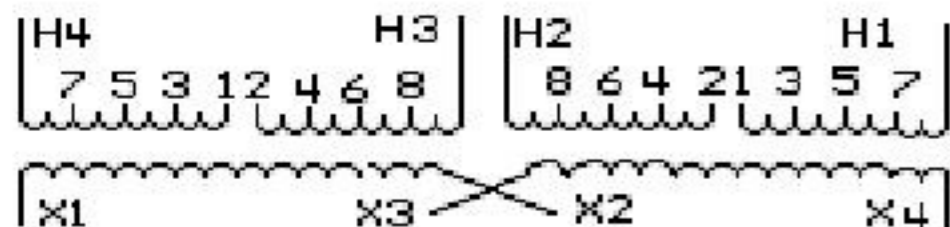

Primary Lines on H1-H4

Volts	Connect
217	7-8
229	5-6
240	3-4
251	1-2

Secondary Lines on X1-X4

Volts	Connect	Volts	Connect
434	7-8	120	X1-X3, X2-X4
446	6-7	240	X2-X3
457	5-6		
469	4-5		
480	3-4		
491	2-3		
503	1-2		

NET WGT
1420 LB
644.1 Kg
YF176
60315
031816

INSPECTION & FINAL TEST
N612!

COIL TAP ARRANGEMENT



LISTED 769G

ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4322G 88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

Outline: 303B932AAP076 Assembled in Mexico


X3 X4 - X2 X1 - -
- - H4 - - H1

Note: Standard

X3 X4 - X2 X1 -
- - H4 - - H1
X3 X4 - X2 X1 -
- - H4 - - H1



2M000000

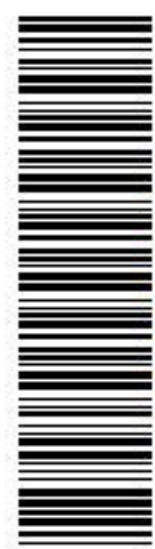

3M000000