



Transformer



Catalog Number **9Q1A037AKAS00A2T00** Type QL

9T83B2702

37.5 KVA 60 HZ 1 PH 8.6 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

PRIMARY LINES ON H1-H2		SECONDARY LINES ON X1-X4	
VOLTS	CONNECT	VOLTS	CONNECT
249	14-H1,13-H2	120	X1-X3,X2-X4
255	12-H1,11-H2	240	X2-X3
264	10-H1,9-H2		
270	8-H1,7-H2		
277	6-H1,5-H2		
285	4-H1,3-H2		
291	2-H1,1-H2		

NET WGT
320 LB


145.2 Kg

50091



070115

INSPECTION
&
FINAL TEST

N5271

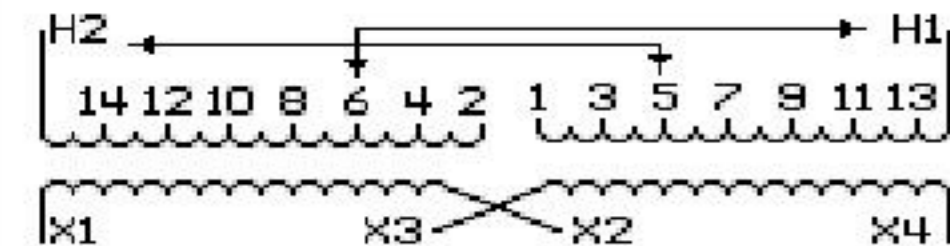

COIL TAP ARRANGEMENT

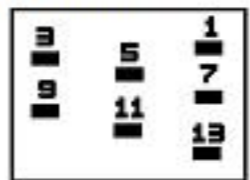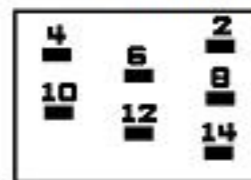

LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R. ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G05

Outline: 303B406AAP071 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X3 - X4 - X2 - X1

- H2 - H1 - -

Note: Standard

X1 -
X2 -
- H1
X4 -
X3 -


-
-
- H2
-
-

-
X2 -
- H1
X4 -
X3 -

-
-
- H2
-
-



2M000000

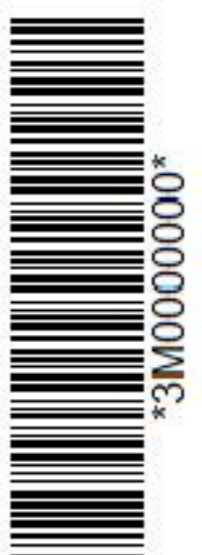

3M000000