

# Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



\*1M000000\*

Catalog Number

Type QL

9T83B2713

50.0 KVA 60 HZ 1 PH 6.7 % IMP


40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

PRIMARY LINES ON X1-X2				SECONDARY LINES ON H1-H4			
VOLTS	CONNECT	VOLTS	CONNECT	VOLTS	CONNECT	VOLTS	CONNECT
109	8-X1,7-X2	218	8-7	240	H1-H3,H2-H4	480	H2-H3
112	6-X1,5-X2	221	7-6				
120	4-X1,3-X2	225	6-5				
128	2-X1,1-X2	233	5-4				
		240	4-3				
		248	3-2				
		255	2-1				

NET WGT  
400 LB  
181.4 Kg  
YF172  
30865  
021216

INSPECTION & FINAL TEST  
N607!

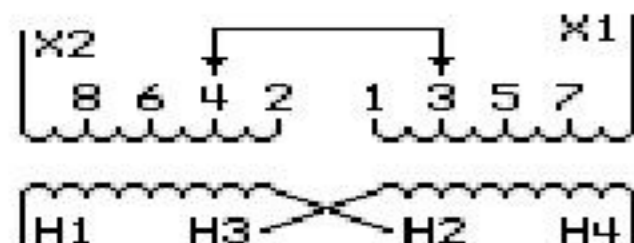

COIL TAP ARRANGEMENT



X2 H4 - X1 H1 -  
- H3 - H2 -  
X2 H4 - X1 H1 -  
- H3 - H2 -



ENCLOSURE TYPE 2 (IP20). RAINPROOF TYPE 3R ENCLOSURE (IP22) WHEN PROVIDED SHIELD 9T18Y4317G06

Outline: 303B406AAP072 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X2 H4 - X1 H1 - -  
- H3 - H2 - -

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

Note: Standard