



# Transformer




Catalog Number **9Q1A015AAAS01A2T00** Type QL

9T83B2760G03

**15.0 KVA 60 HZ 1 PH 3 % IMP**

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

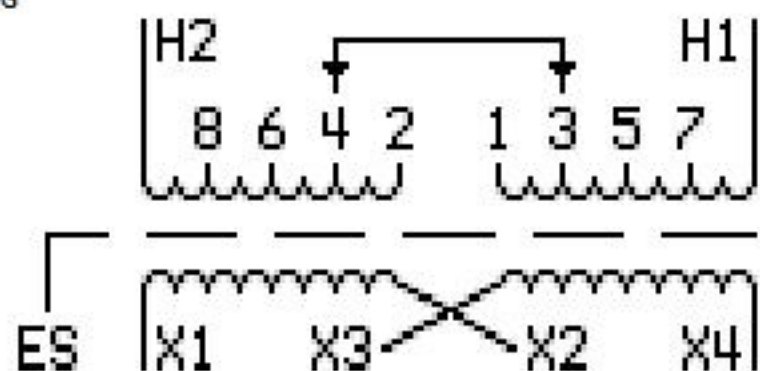

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

PRIMARY				SECONDARY	
UOLTS	CONNECT	UOLTS	CONNECT	UOLTS	CONNECT
216	8-H1,7-H2	432	8-7	120	X1-X3,X2-X4
228	6-H1,5-H2	444	7-6	240	X2-X3
240	4-H1,3-H2	456	6-5		
252	2-H1,1-H2	468	5-4		
		480	4-3		
		492	3-2		

NET WGT  
320 LB  
145.2 Kg  
50070  
070115

INSPECTION & FINAL TEST  
N5271

### COIL TAP ARRANGEMENT



LISTED 769G

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G05

Outline: 303B406AAP071 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

X3 - X4 - X2 - X1

- H2 - H1 - -

Note: Standard

X1 - - -  
X2 - - -  
X3 - - -  
X4 - - -  
H1 - - -  
H2 - - -

X1 - - -  
X2 - - -  
X3 - - -  
X4 - - -  
H1 - - -  
H2 - - -

\*2M000000\*  
\*3M000000\*