



Transformer




Catalog Number **9Q1A015AGAS01A2T00** Type QL

9T83B2790G03

15.0 KVA 60 HZ 1 PH 5.2 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

NOG

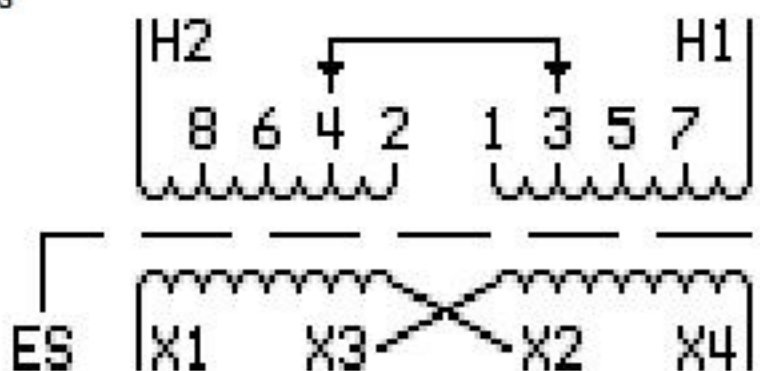

ELECTROSTATIC GROUND SHIELD IN EACH PHASE

9T83B2675G159T83B2675G15 150921KK
 E 303B932AAP075 YNNN 40115220IS-19CQL 1 60AL100109N100.0
 6.5 900 820 240x480(+2,-4 2.30%120/240 E1 I
 09T18Y4322G77615020NN 2FD3TRBGENSALE07831731671901475A1221EAG
 001 N01 NYF175GENSALE0 100.000240x480(+2,-4 2.30%)
 120/240 0705NN N9T18Y43
 22G77TRANSFORMER ENERGY-NOG H0 0 ANC4

5113000061000000

SECONDARY		PRIMARY	
LINES ON X1-X4	VOLTS CONNECT	LINES ON H1-H2	VOLTS CONNECT
270	8-H1,7-H2	540	8-7

NET WGT
320 LB
145.2 Kg
57744
092115

INSPECTION & FINAL TEST
N539!

COIL TAP ARRANGEMENT



Outline: 303B406AAP071 Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL


IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

Note: Standard

X1 - - -
 X2 - - -
 X3 - - -
 X4 - - -
 H1 - - -
 H2 - - -



2M000000

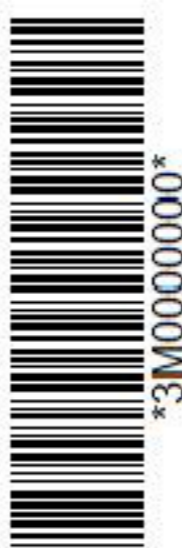

3M000000