




# Transformer

Catalog Number 9T83B3389

**9Q3A500AAAZ00A2T00**

**500.0 KVA 60 HZ 3 PH 4.9 % IMP**

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL

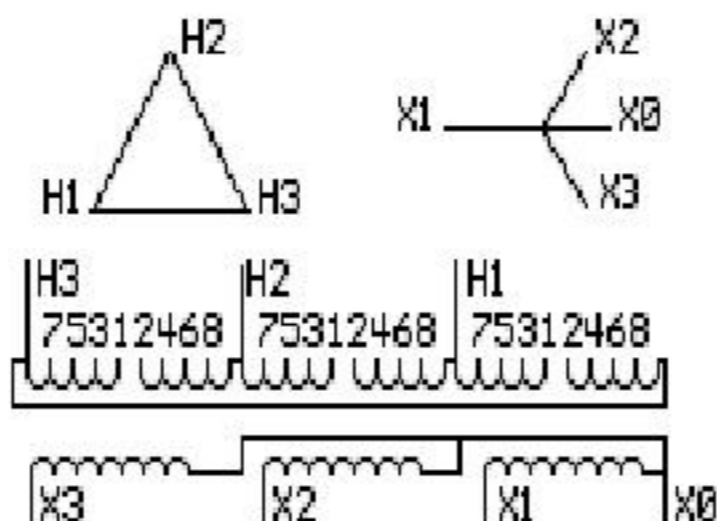


### JUMPER CONNECTION

TAP	VOLTS
1-2	508
2-3	489
3-4	480
4-5	469
5-6	459
6-7	440
7-8	430

PRIMARY (H) 480 VOLTS (LINE-LINE)  
 SECONDARY (X) 220 VOLTS (LINE-LINE)  
 127 VOLTS (LINE-NEUTRAL)

### COIL TAP ARRANGEMENT

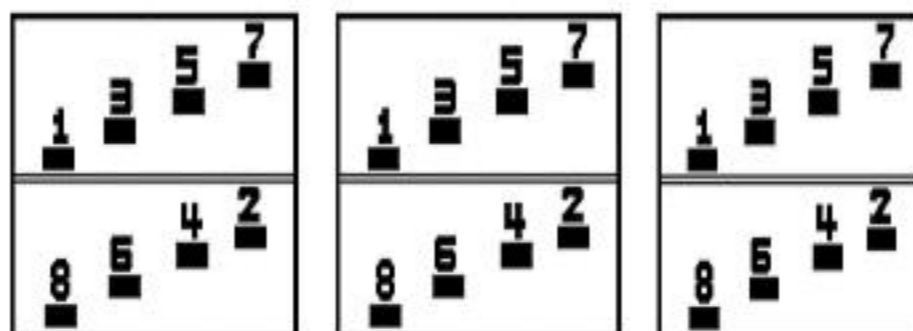

NET WGT 3400 LB 1542.2 Kg

102715 N544! YF379  
 58079 NOG



ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES  
 CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B919AAP179  
 Assembled in Mexico

INSPECTION & FINAL TEST  
 N544!