




# Transformer

Catalog Number **9T83B3557**

**225.0 KVA 60 HZ 3 PH 4 % IMP**

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: Q1

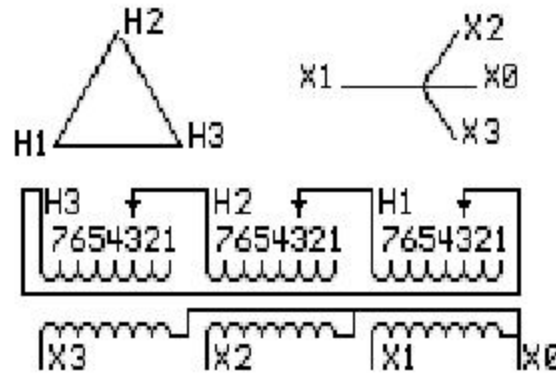


### JUMPER CONNECTION

TAP	VOLTS
1	506
2	493
3	480
4	466
5	459
6	446
7	433

PRIMARY (H) 480 VOLTS (LINE-LINE)  
 SECONDARY (X) 415 VOLTS (LINE-LINE)  
 240 VOLTS (LINE-NEUTRAL)


### COIL TAP ARRANGEMENT

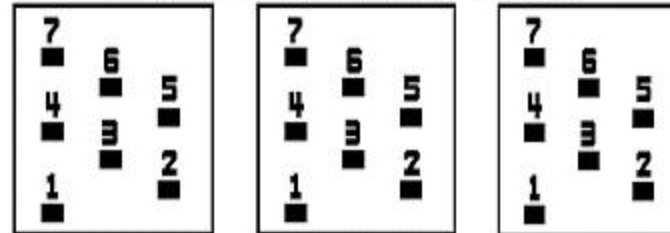

NET WGT 1585 LB 719.0 Kg

111411 N147! FC79

9T83B3557 15731 NOG

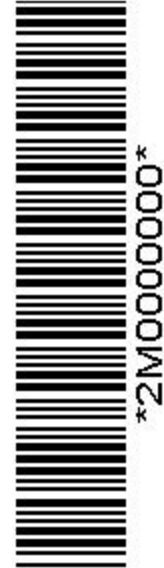

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G79

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B919AAP077  
Assembled in Mexico

INSPECTION & FINAL TEST  
N147!