



Transformer


Catalog Number 9T83B3818G50

9Q3A300AEAA00A2T30

300.0 KVA 60 HZ 3 PH 7.2 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C Type: QL


PRIMARY (H) 240 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
120 VOLTS (LINE-NEUTRAL)

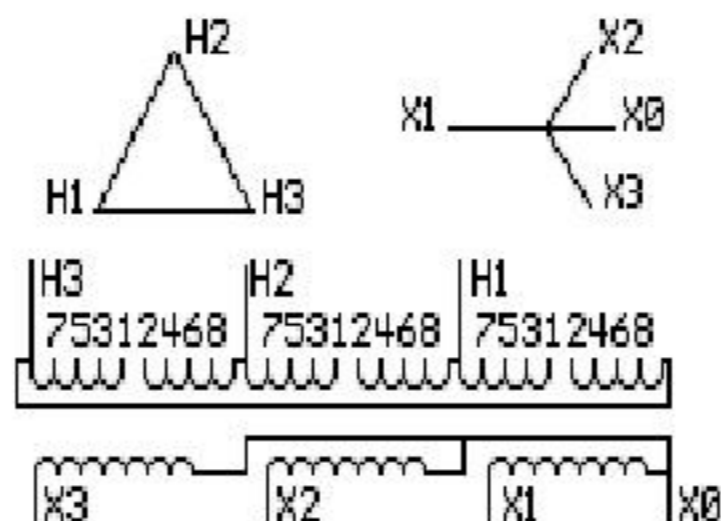

JUMPER CONNECTION

TAP	VOLTS
1-2	252
2-3	246
3-4	240
4-5	234
5-6	229
6-7	223
7-8	217

COIL TAP ARRANGEMENT

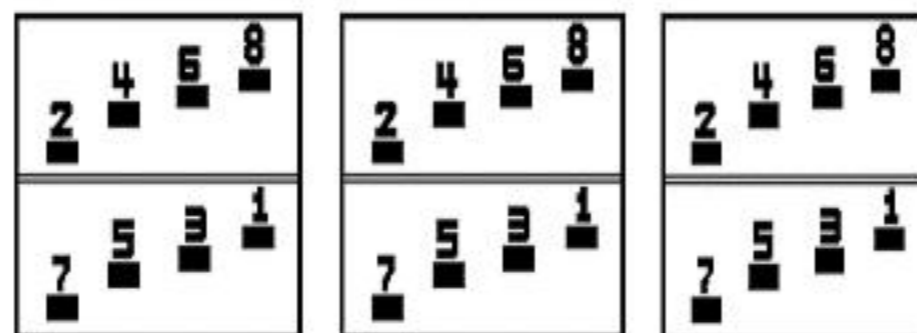

NET WGT 2016 LB 914.5 Kg

102315 N543! YF378
58061 NOG



ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G88

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B919AAP178
Assembled in Mexico

INSPECTION & FINAL TEST
N543!