



# Transformer


Catalog Number

**9T83B3879G99**

**500.0 KVA    60 HZ    3 PH    4.4 % IMP**

40 C AMB.    150 C RISE    220 C SYSTEM    IS-19C    Type: QL


PRIMARY (H)    480 VOLTS (LINE-LINE)  
SECONDARY (X)    208 VOLTS (LINE-LINE)  
                          120 VOLTS (LINE-NEUTRAL)

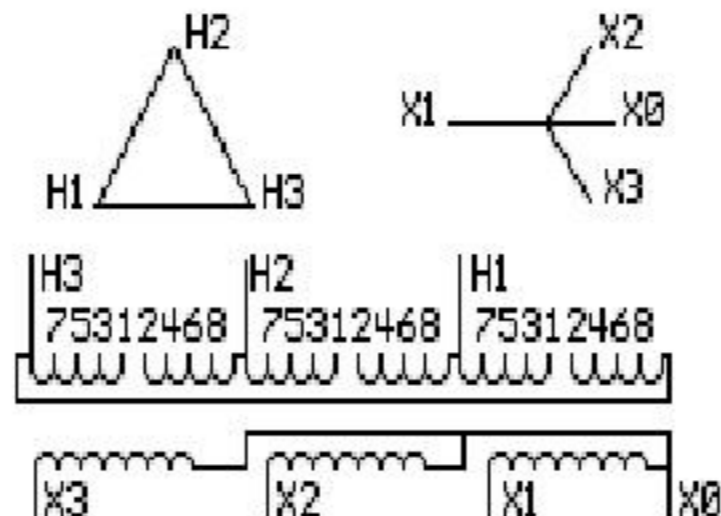


### JUMPER CONNECTION

TAP	VOLTS
1-2	500
2-3	490
3-4	480
4-5	470
5-6	460
6-7	440
7-8	430

### COIL TAP ARRANGEMENT

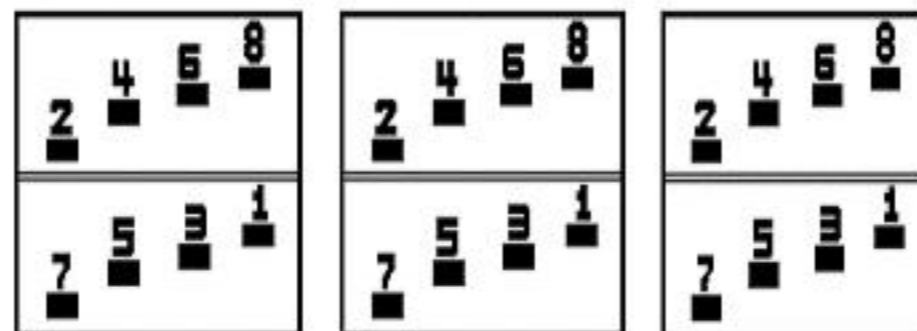

NET WGT 2265 LB    1027.4 Kg  
100815    N541!    L39AA  
                  57944    NOG

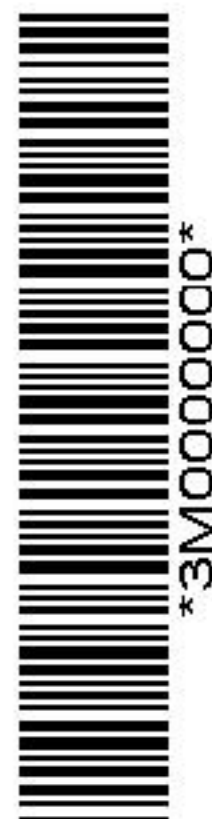

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4322G68

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR    PRIMARY: 10 KV BIL    SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.



Outline: 303B912AAP179    INSPECTION & FINAL TEST  
Assembled in Mexico    N541!