

# GE Drive Isolation Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



\*1M0000000\*


Catalog Number **Type QL**

**9T83B4000G20**


**15.0 KVA 60 HZ 3 PH 5.6 % IMP**

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)  
 SECONDARY (H) 460 VOLTS (LINE-LINE)  
 266 VOLTS (LINE-NEUTRAL)

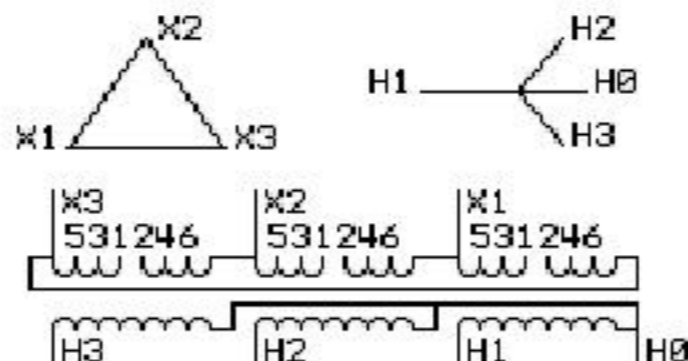

### COIL TAP ARRANGEMENT

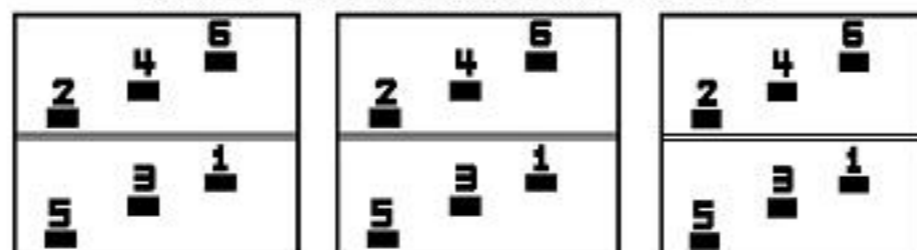

JUMPER CONNECTION	
TAP	VOLTS
1-2	219
3-4	208
5-6	198

NET WGT  
240 LB  
108.9 Kg

54489  
XU371  
NOG  
123015

INSPECTION  
&  
FINAL TEST  
N553!



ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G11

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001 Outline: 303B401AAP071  
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

Note:

H3 - H2 - H1 - -  
 - X3 - X2 - X1



\*2M0000000\*



\*3M0000000\*

H3 - H2 - H1 - -  
 - X3 - X2 - X1  
 H3 - H2 - H1 - -  
 - X3 - X2 - X1

H0