



Transformer



1M000000


Catalog Number
9T83B4000G21

Type **QL**

15.0 KVA 60 HZ 3 PH 5.4 % IMP

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)
SECONDARY (H) 230 VOLTS (LINE-LINE)
133 VOLTS (LINE-NEUTRAL)

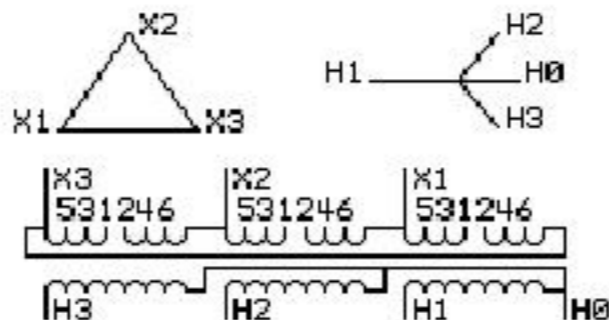

JUMPER CONNECTION TAP VOLTS


1-2	218
3-4	208
5-6	198

NET WGT
240 LB
108.9 Kg

54490
XV371
NOG
071615

INSPECTION & FINAL TEST
N529!

COIL TAP ARRANGEMENT

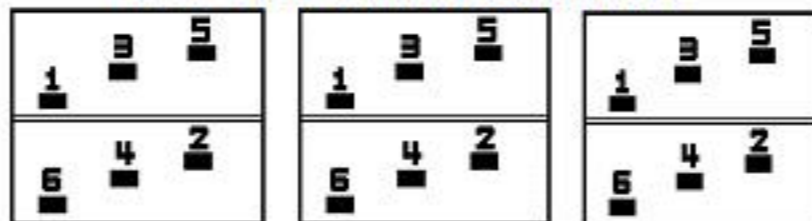

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G11

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

Outline: 303B401AAP071

IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

H3 - H2 - H1 - -
- X3 - X2 - X1

Note:

H1 - H0
H2 - X1
H3 - X2
H3 - H2 - H1 - H0
X3 - X2 - X1

