

# GE Drive Isolation Transformer

NEMA CLASS AA DRY TYPE TRANSFORMER



\*1M0000000\*

Catalog Number **Type QL**

**9D3A015AFBU00A2T00**


**9T83B4000G92**

**15.0 KVA 60 HZ 3 PH 6.3 % IMP**


**40 C AMB. 150 C RISE 220 C SYSTEM IS-19C**

**PRIMARY (H) 208 VOLTS (LINE-LINE)**

**SECONDARY (X) 208 VOLTS (LINE-LINE)**

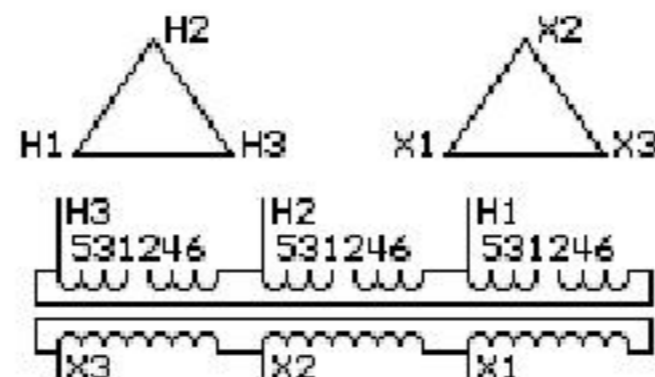

### COIL TAP ARRANGEMENT

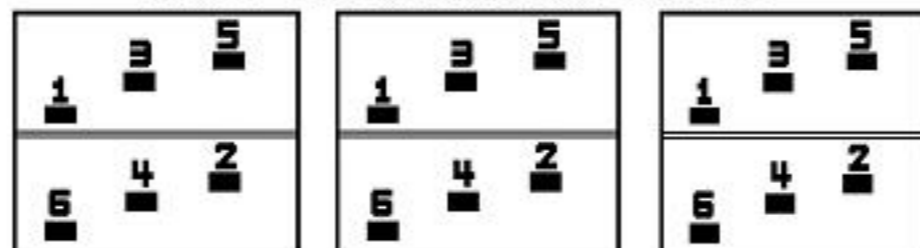

JUMPER CONNECTION	
TAP	VOLTS
1-2	218
3-4	208
5-6	198

NET WGT  
240 LB  
108.9 Kg

58943

KU371

NOG

010416

INSPECTION  
&  
FINAL TEST  
N602!



ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G11

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001

Outline: 303B401AAP071

ALUMINUM CONDUCTOR


PRIMARY: 10 KV BIL

SECONDARY: 10 KV BIL


IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.

X3 - X2 - X1 - -  
- H3 - H2 - H1

Note: Standard

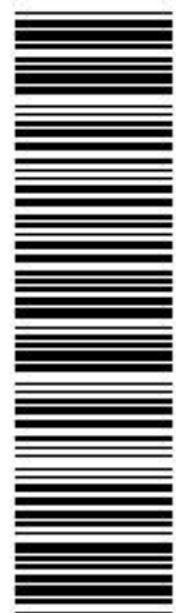

\*2M0000000\*

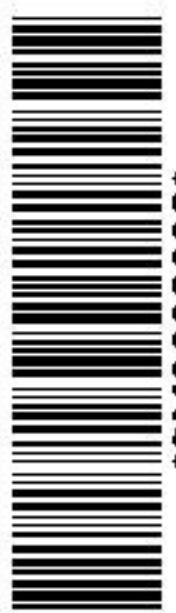

\*3M0000000\*

X3 - X2 - X1 -  
- H3 - H2 - H1  
X3 - X2 - X1 -  
- H3 - H2 - H1