



# Transformer



\*1M000000\*


Catalog Number  
**9T83B4000G99**

Type **QL**


**15.0 KVA 60 HZ 3 PH 5.6 % IMP**

40 C AMB. 150 C RISE 220 C SYSTEM IS-19C

PRIMARY (X) 208 VOLTS (LINE-LINE)  
SECONDARY (H) 460 VOLTS (LINE-LINE)  
265 VOLTS (LINE-NEUTRAL)

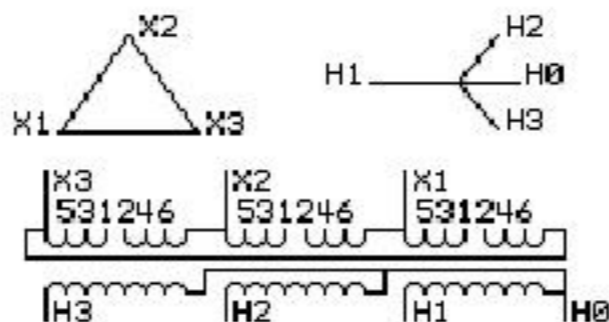

### COIL TAP ARRANGEMENT

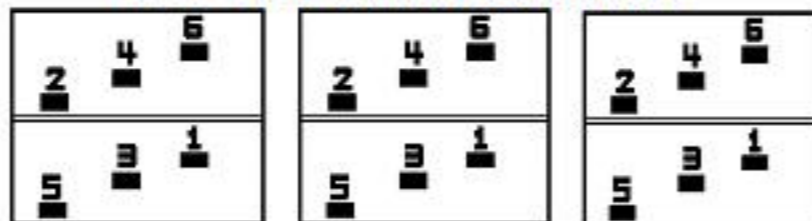

JUMPER CONNECTION	
TAP	VOLTS
1-2	219
3-4	208
5-6	198

NET WGT  
240 LB  
108.9 Kg

54501  
XV371  
NOG  
071615

INSPECTION  
&  
FINAL TEST  
N529!

ENCLOSURE TYPE 2 (IP30). RAINPROOF TYPE 3R ENCLOSURE (IP32) WHEN PROVIDED SHIELD 9T18Y4317G11

Assembled in Mexico

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001  
ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL

Outline: 303B401AAP071

**IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION. CHECK ADDITIONAL NEC AND LOCAL CODES.**

H3 - H2 - H1 - -  
- X3 - X2 - X1

Note:

H1 - - - H0  
H2 - - - X1  
H3 - - - X2  
H3 - - - X3  
H3 - - - X1  
H3 - - - X2  
H3 - - - X3



\*2M000000\*



\*3M000000\*